


# Swivel elbows

Directionally adjustable taper coupling

Tube coupling: VOSS Lok 40

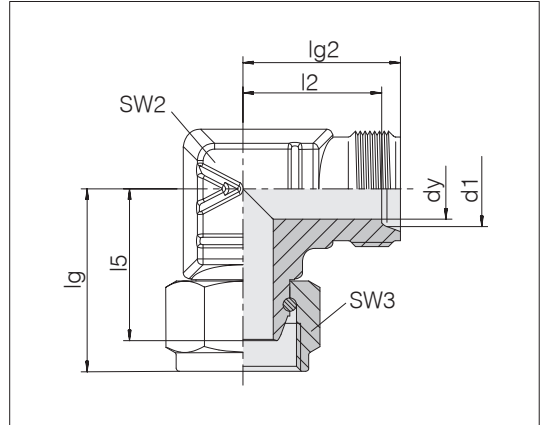

Tube OD d1	dy	lg	lg2	l2	l5	SW2	SW3	kg/100 ca.	Order-No.	Designation
6	4.5	25.8	20.8	18.2	20.6	12	14	3.8	7005172700	40-SWE-6-SST
8	6.5	26.7	21.8	19.1	21.6	14	16	5.6	7005172800	40-SWE-8-SST
10	8	29.1	23.8	20.8	23.8	17	19	7.2	7005172900	40-SWE-10-SST
12	9.5	33.4	27.3	24.2	27.7	19	22	10.6	7005173000	40-SWE-12-SST
14	11.5	36.3	30.3	27.1	30.7	22	25	17.7	7005173100	40-SWE-14-SST
15	12	36.3	30.3	27	30.8	22	25	14.8	7005173200	40-SWE-15-SST
16	13	36.1	30.3	26.8	30.8	22	25	13.9	7005173300	40-SWE-16-SST
18	15	39	32.6	29	33.3	27	30	26.4	7005173400	40-SWE-18-SST
20	16	40.3	34	30.3	34.7	30	32	30.0	7005173500	40-SWE-20-SST
22	18	40	34	30	34.7	30	32	27.4	7005173600	40-SWE-22-SST