


# Unions

Tube coupling: VOSS Lok 40

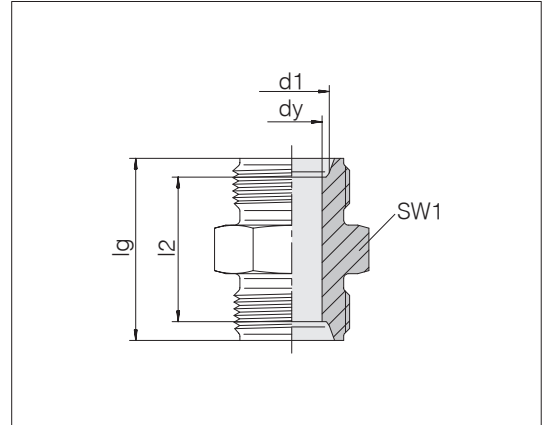

Tube OD d1	dy	lg	l2	SW1	kg/100 ca.	Order-No.	Designation
6	4.5	25	19.8	12	1.4	7000935900	40-S-6-SST
8	6.5	26	20.6	14	1.7	7000936000	40-S-8-SST
10	8	26	20	17	2.7	7000936100	40-S-10-SST
12	10	28	21.8	22	4.5	7000936200	40-S-12-SST
14	11.5	28	21.6	24	6.0	7000936300	40-S-14-SST
15	12	28	21.4	24	5.7	7000936400	40-S-15-SST
16	13	28	21	24	5.1	7000936500	40-S-16-SST
18	15	30	22.8	27	7.3	7000936600	40-S-18-SST
20	16	30	22.6	30	9.6	7000936700	40-S-20-SST
22	18	30	22	30	8.2	7000936800	40-S-22-SST