







## Jack 1000

with height adjustment via crank handle,  
load capacity: 1000kg

| Nr.   | A   | B  | C   | D   | E  | F   | G   | H   | I  |        |
|-------|-----|----|-----|-----|----|-----|-----|-----|----|--------|
| 92949 | 150 | 76 | 100 | M12 | 25 | 175 | 250 | 265 | 20 | 10.115 |

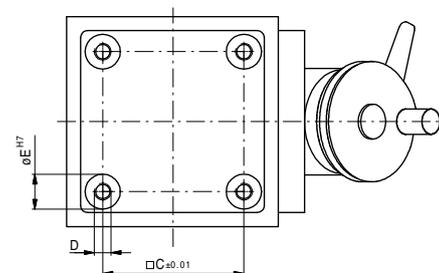

Top blocks are not included in jack supply, they must be ordered separately.

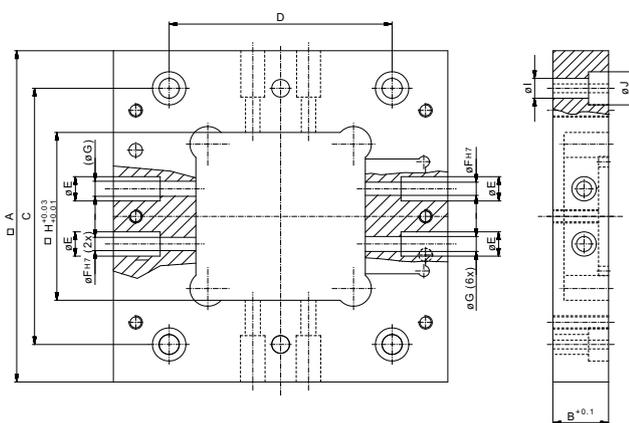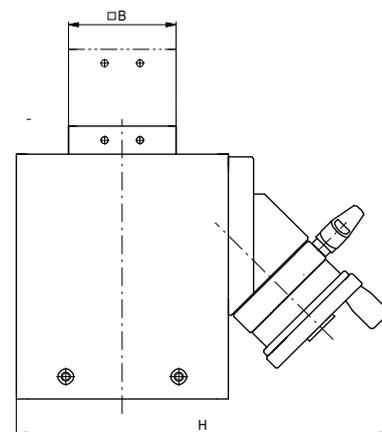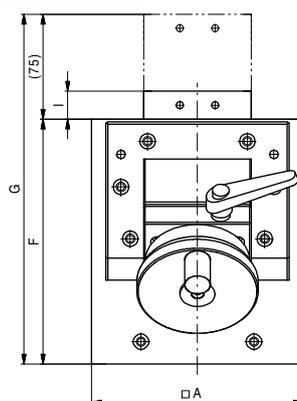

## Top block

for jack 92949

| Nr.   | A   | B  | C   | D   | E  | F | G   | H  | I | J  |       |
|-------|-----|----|-----|-----|----|---|-----|----|---|----|-------|
| 50219 | 150 | 25 | 116 | 100 | 11 | 6 | 6,8 | 76 | 9 | 15 | 1.200 |



Top blocks are not drilled but can be supplied with customized grid on request



**ALUFIX CLASSIC** elements can be anodized in different colours. The colour natural is standard, black (-1) is available as an alternative. Other colours on request.