


## Roller slide

adjustment using a screw spindle

Nr.	A (AF)	B	max. load	shift	
82453	16	M4	20 kg	±9	89
82172	25	M6	50 kg	±13,5	242
82173	40	M10	150 kg	±22	970
82398	50	M12	250 kg	±27	1.910

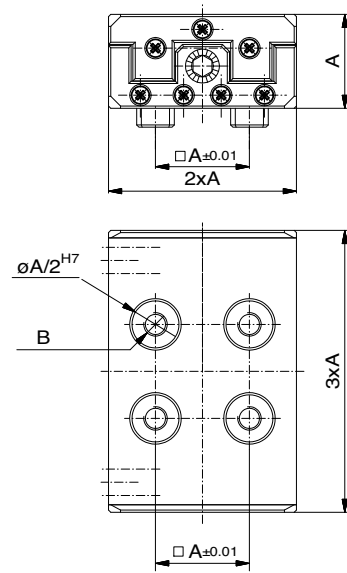


## Cross roller slide

adjustment using a screw spindle

Nr.	A (AF)	B	max. load	shift	
82461	16	M4	20 kg	±9	178
82462	25	M6	50 kg	±13,5	484
82463	40	M10	150 kg	±22	1.940
82399	50	M12	250 kg	±27	3.820



Roller slides and cross roller slides can be optionally equipped with rotating knob/s

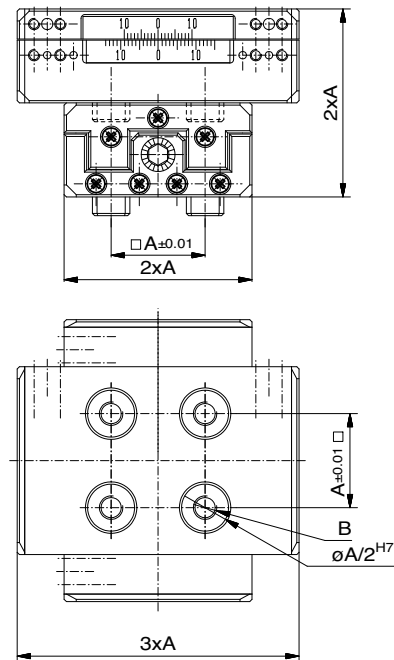

**ALUFIX CLASSIC** elements can be anodized in different colours. The colour natural is standard, black (-1) is available as an alternative. Other colours on request.

Other dimensions on request