


Witte heavy duty slides are available with slide bearing or roller bearing. Slides with roller bearing can cope with a higher load capacity lauf with free floating operation

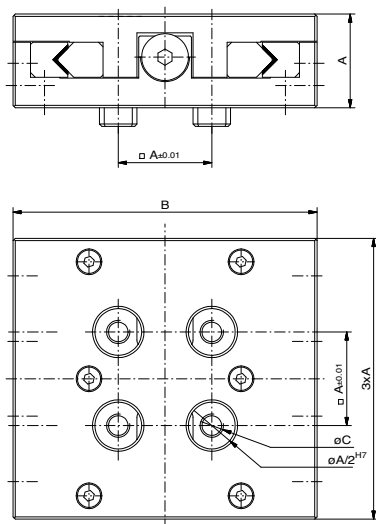

## Guiding slide, heavy duty

guided with slide bearings

Nr.	A (AF)	B	C	max. load	shift	
92364	25	79	M6	75 kg	+/- 12,5	450
92423	40	130	M10	225 kg	+/- 20	2.000
92424	50	158	M12	375 kg	+/- 25	3.500

guided with roller bearings

Nr.	A (AF)	B	C	max. load	shift	
280495	25	79	M6	150 kg	+/- 13	450
280496	40	130	M10	450 kg	+/- 21	2.000
280497	50	158	M12	750 kg	+/- 26	3.500



Version with slide bearings



Application example:  
Anodized black with positioning pin and guide mounted